



Summary

[Request a quote](#)

[Catalog](#)

| | |
|------------------------------------|--------------------------------|
| Coax | 1 |
| Plug | Plug - Elbow |
| Locking system | Push-pull |
| Jacket cable outside diameter [mm] | 2.80 - 3.10 mm |
| Matching parts | ERA.00.250.CTL |
| Series | 00 - NIM-CAMAC |

Technical details

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fla-00-250-ctac31z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

| | |
|----------------------------|------------------------------|
| Coax | 1 |
| Contact Termination Coax | Solder |
| R (max) | 6.1 mOhm |
| Insert configuration value | 0.25 - 1 Coax (50 Ohm) |
| Insulator | T: PTFE |
| Rated current | 4 Amps |
| Impedance | 50 Ohm |
| VSWR | $1.09 + 0.11 * f/\text{GHz}$ |
| Vtest | 2100 V (AC), 3000 V (DC) |
| Contact Type | Coaxial 50 Ohm (Solder) |
| Test voltage | 2.1 kV (rms) |
| Cable type | Cable type: A RG 179 B/U S |
| Bucket Dia. | 0.6 mm (0.024in) |
| Contact Dia. | 0.7 mm (0.028in) |

Form & Material

| | |
|------------------------|---|
| Shell style / Model id | FLA - Elbow plug, cable collet and nut for fitting a bend relief |
| Plug | Elbow |
| Housing material | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Push-pull |
| Keying | Circular, male |
| Variant | Nut for fitting a bend relief |
| Weight | 5.4 g |

Environment

| | |
|--------------------------------------|----------|
| Environmental protection (IP rating) | IP50 |
| F ret (min) | 100 N |
| Salt Spray Corrosion | >1000 hr |


https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fla-00-250-ctac31z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

| | |
|------------------------------------|-----------------------|
| Cable termination protection | For cable bend relief |
| Fixation type | Cable collet |
| Jacket cable outside diameter [mm] | 2.80 - 3.10 mm |

Drawings

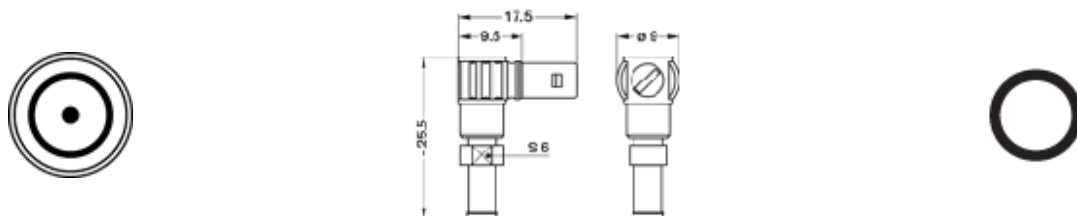

Dimensions

| | A | L | M | S2 |
|-----|------|------|------|------|
| mm. | 9 | 17.5 | 9.5 | 4.5 |
| in. | 0.35 | 0.69 | 0.37 | 0.18 |

Recommended By Lemo

Accessories

Tools

Spanner wrench

[DCD.00.ZZZ.PA060](#)

Cables

| Cable PartNumber | Material | Colour | Cable image |
|--------------------|----------|--------|-------------|
| 17420 | PVC | Black | |
| 31600 | PTFE | Brown | |
| CCX.50.RG1.74AU28N | PVC | Black | |
| CCX.50.RG1.74AU28N | PVC | Black | |
| CCX.50.RG3.16U28M | PTFE | Brown | |

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fla-00-250-ctac31z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.